

## Product data sheet


### Characteristics

# 05050

## big junction box - IP 55 - smooth faces - 193 x 164 mm

### Main

|              |                       |
|--------------|-----------------------|
| Box category | Big size junction box |
|--------------|-----------------------|

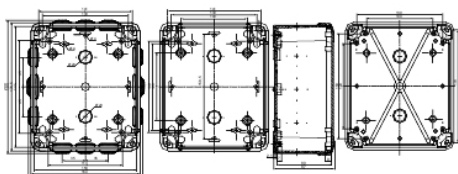

### Complementary

|                  |                    |
|------------------|--------------------|
| Colour           | Grey               |
| Colour code      | RAL 7035           |
| Cover fixing     | Quarter turn screw |
| Cable entry      | Smooth faces       |
| Housing material | Polypropylene      |
| Device mounting  | Surface            |
| Internal height  | 175 mm             |
| Internal width   | 150 mm             |
| Internal depth   | 80 mm              |
| Height           | 193 mm             |
| Width            | 164 mm             |
| Depth            | 87 mm              |



### Environment

|                                       |            |
|---------------------------------------|------------|
| IP degree of protection               | IP55       |
| IK degree of protection               | IK07       |
| Ambient air temperature for operation | -5...40 °C |



### Packing Units

|                  |            |
|------------------|------------|
| Package 1 Weight | 0.380 kg   |
| Package 1 Height | 88.000 mm  |
| Package 1 width  | 162.000 mm |
| Package 1 Length | 140.000 mm |

### Offer Sustainability

|                        |  |
|------------------------|--|
| RECh Regulation        |  <a href="#">RECh Declaration</a>   |
| RECh free of SVHC      | Yes  |
| EU RoHS Directive      | Pro-active compliance (Product out of EU RoHS legal scope)  <a href="#">EU RoHS Declaration</a> |
| Toxic heavy metal free | Yes  |
| Mercury free           | Yes  |

---

|                            |  |
|----------------------------|--|
| RoHS exemption information |  Yes                     |
| China RoHS Regulation      |  China RoHS Declaration |

---

### Contractual warranty

---

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

---