

Product data sheet


Characteristics

05057

Mureva Surface Mounted Boxes, Mureva Box, 291 x 241 x 127mm, IP55, Halogen Free

Main

Box category	Big size junction box
--------------	-----------------------

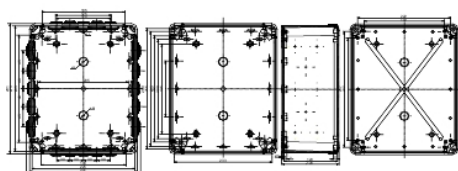

Complementary

Colour	Grey
Colour code	RAL 7035
Cover fixing	Quarter turn screw
Cable entry	Smooth faces
Housing material	Polypropylene
Device mounting	Surface
Internal height	275 mm
Internal width	225 mm
Internal depth	120 mm
Height	291 mm
Width	241 mm
Depth	128 mm

Environment

IP degree of protection	IP55
IK degree of protection	IK07
Ambient air temperature for operation	-5...40 °C

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	13 cm
Package 1 Width	23.8 cm
Package 1 Length	28.6 cm
Package 1 Weight	1.012 kg

Offer Sustainability

REACH Regulation	 REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes
Circularity Profile	No need of specific recycling operations

Contractual warranty

Warranty	18 months
----------	-----------