


Product data sheet

Characteristics

1208016

Spring Toggle Cavity fixing

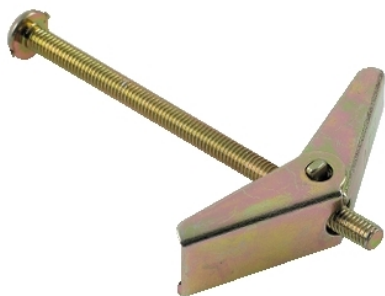

Main

Range of product	Thorsman
Product or component type	Cavity fixing
Product name	Thorsman TOG
Device short name	TOG
Provided equipment	Screw
Mounting support	Board material
Device application	Board material
Mounting support	Wall mounted
Thread type	M3
Screw diameter	3 mm
Screw length	50 mm
Drilling diameter	11 mm
Colour tint	Metal

Complementary

Quantity per set	Set of 50
Sale per indivisible quantity	50

Environment

Material	Screw: steel electroplated Cavity fixing: sheet metal electroplated
Practical load capacity	Pull-out load: 100 N for 13 mm plasterboard
Thickness	0...30 mm fixture
Environmental characteristic	Fire resistance

Packing Units

Package 1 Weight	5.000 g
Package 1 Height	34.000 mm
Package 1 width	7.000 mm
Package 1 Length	60.000 mm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile