


Product data sheet

Characteristics

1439SHD-TR

PG TP 250V 10A H/DTY PGTP I.PN

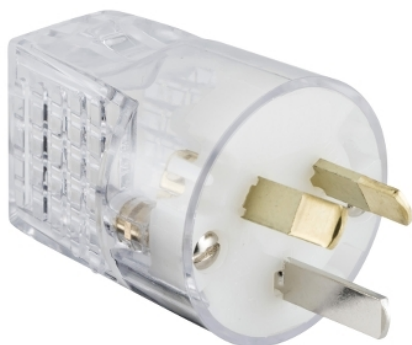

Main

Range of product	Standard Series
Product brand	Clipsal

Complementary

[In] rated current	10 A
[Ue] rated operational voltage	230 V 50/60 Hz conforming to EN 60309-2
Colour	Body: transparent
Material	Plastic
Connections - terminals	Screw terminal
Plug, socket, control station shape	Straight
Duration	6 h

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	0.044 kg
Package 1 Height	72 mm
Package 1 width	41 mm
Package 1 Length	41 mm
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Weight	0.58 kg
Package 2 Height	8.4 cm
Package 2 width	12.65 cm
Package 2 Length	17 cm
Unit Type of Package 3	CAR
Number of Units in Package 3	200
Package 3 Weight	11.6 kg
Package 3 Height	25.4 cm
Package 3 width	34.8 cm
Package 3 Length	44.5 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile