


## Product data sheet

### Characteristics

# 30RJ64SMT-WE

## SOCKET MOD 6W/4C MECH TELE

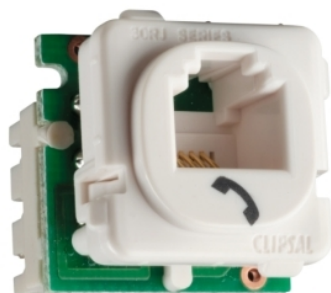

### Main

Colour	White electric
Product brand	Clipsal
Range of product	Actassi
Product or component type	Socket-outlet

### Complementary

Colour code	WE
Number of ways	6 ways
Connector type	110 RJ11
Communication network category	3
Fixing mode	Special tool
AWG gauge	AWG 26...AWG 22

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	8.0 g
Package 1 Height	2.4 cm
Package 1 width	2.3 cm
Package 1 Length	2.8 cm
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Weight	0.098 kg
Package 2 Height	4.4 cm
Package 2 width	5.6 cm
Package 2 Length	12 cm
Unit Type of Package 3	PAL
Number of Units in Package 3	28000
Package 3 Weight	240000.0 g
Package 3 Height	90 cm
Package 3 width	116.5 cm
Package 3 Length	116.5 cm

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>