


## Product data sheet

### Characteristics

# 30RJ64SMT-WE

Clipsal Actassi, Modular Socket, Category 3, 6 Way, 4 Contact Socket Mechanism, Telephone

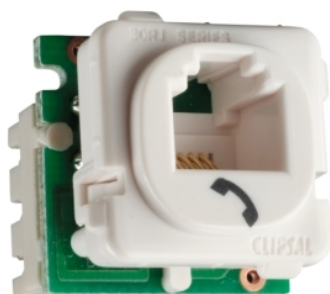

### Main

Colour	White electric
Product brand	Clipsal
Range of product	Actassi
Product or component type	Socket-outlet

### Complementary

Colour code	WE
Number of ways	6 ways
Connector type	110 RJ11
Communication network category	3
Fixing mode	Special tool
AWG gauge	AWG 26...AWG 22

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.4 cm
Package 1 Width	2.3 cm
Package 1 Length	2.8 cm
Package 1 Weight	8 g

### Offer Sustainability

Sustainable offer status	Green Premium product
RECh Regulation	<a href="#">RECh Declaration</a>
RECh free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	No need of specific recycling operations