


Product data sheet

Characteristics

40E1USBM-VW

Clipsal Iconic, Single USB Charging Mechanism, 1.5 A Horizontal/Vertical Mount

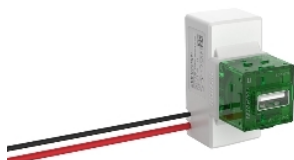

Main

Range	Clipsal Iconic
Product or component type	USB charger
[Ue] rated operational voltage	220/240 V AC 50 Hz
Integrated connection type	1 USB 2.0 type A 5 V DC, maximum load current: 1.5 A
Maximum load current with 2 outputs used simultaneously	1.5 A

Complementary

Device mounting	Flush
Device presentation	Mechanism
Colour tint	Vivid white
Surface finish	Glossy
Fixing mode	Clipped
Sale per indivisible quantity	1
Ambient air temperature for operation	0...45 °C
Ambient air temperature for storage	0...60 °C
Relative humidity	5...90 %
Number of terminals	1 with cable end
Height	48 mm
Width	43 mm
Depth	43 mm
Embedding depth	38 mm

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4.2 cm
Package 1 Width	6.5 cm
Package 1 Length	9 cm
Package 1 Weight	75.6 g
Unit Type of Package 2	BB1
Number of Units in Package 2	6
Package 2 Height	13 cm
Package 2 Width	9.6 cm
Package 2 Length	15.2 cm
Package 2 Weight	626 g
Unit Type of Package 3	CAR
Number of Units in Package 3	72
Package 3 Height	34.1 cm

Package 3 Width	26.4 cm
Package 3 Length	33.8 cm
Package 3 Weight	7984 g

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information