


Product data sheet

Characteristics

4MSW3100

Clipsal MAX4, Main Switch 3P 100A 415 V

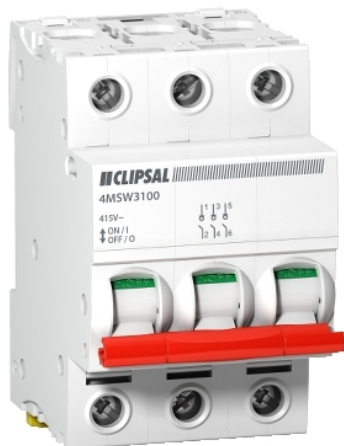

Main

Product brand	Clipsal
---------------	---------

Complementary

Product or component type	Switch disconnector
[Ue] rated operational voltage	<= 415 V AC
[In] rated current	100 A
Rated conditional short-circuit current	10 kA
Number of poles	3
Mounting support	DIN rail

Environment

IP degree of protection	Front face: IP20
-------------------------	------------------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	8.5 cm
Package 1 Width	5.4 cm
Package 1 Length	7.5 cm
Package 1 Weight	240.0 g

Offer Sustainability

EU RoHS Directive	Under investigation
-------------------	---------------------

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.