


Product data sheet

Characteristics

4PSW340

Switch disconnecter, MAX4, 3P, 40 A, 415 V

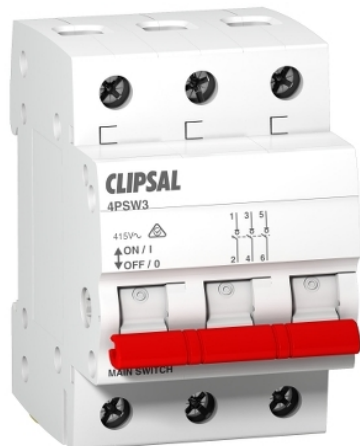

Main

| | |
|------------------|----------|
| Range of product | Series 4 |
| Product brand | Clipsal |

Complementary

| | |
|--------------------------------|---------------------|
| Product or component type | Switch disconnecter |
| [Ue] rated operational voltage | <= 415 V AC |
| [In] rated current | 40 A |
| Number of poles | 3 |
| Mounting support | DIN rail |

Environment

| | |
|-------------------------|------------------|
| IP degree of protection | Front face: IP20 |
|-------------------------|------------------|

Packing Units

| | |
|------------------|-----------|
| Package 1 Weight | 228.000 g |
| Package 1 Height | 90.000 mm |
| Package 1 width | 55.000 mm |
| Package 1 Length | 80.000 mm |

Offer Sustainability

| | |
|----------------------------|---|
| Sustainable offer status | Green Premium product |
| REACH Regulation | REACH Declaration |
| REACH free of SVHC | Yes |
| EU RoHS Directive | Compliant EU RoHS Declaration |
| Toxic heavy metal free | Yes |
| Mercury free | Yes |
| RoHS exemption information | Yes |
| China RoHS Regulation | China RoHS Declaration |
| Environmental Disclosure | Product Environmental Profile |
| Circularity Profile | End Of Life Information |