


## Product data sheet

### Characteristics

# 56P3/110-EO

Clipsal - 56 Series, Plug Top, Straight, 3 PIN, 10A, 110V, IP66

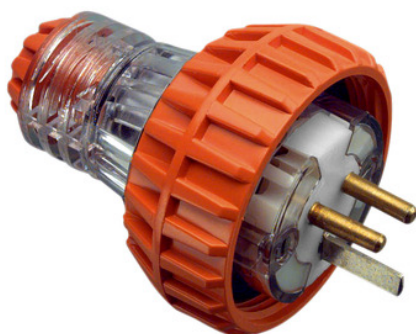

#### Main

Range	Clipsal - 56 Series
Range of product	Series 56
Product brand	Clipsal
Product or component type	Plug
Device application	Power supply

#### Complementary

[In] rated current	10 A
Poles description	1P + N + E
[Ue] rated operational voltage	110 V AC 50 Hz conforming to EN 60309-2
Colour	Orange (RAL 2004)
Material	Plastic
Plug, socket category	Low voltage
Material	Polycarbonate: housing
Outlet standard	Industrial
Connections - terminals	Screw terminal 0.75...1 mm <sup>2</sup>
Wire stripping length	35 Mm 10 mm
Contacts material	Pins: brass
Cable entry	Cable gland
Thread type	M20
Plug, socket, control station shape	Straight
Quality labels	RCM
Pin arrangement	J
Service life in hours	4 h
Net weight	0.12 kg
Height	67 mm
Width	67 mm
Depth	112.5 mm
Targeted country	Australia

#### Environment

Standards	AS/NZS 3112
IP degree of protection	IP66 conforming to AS 60529
Ambient air temperature for operation	-25...75 °C

## Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7 cm
Package 1 Width	7 cm
Package 1 Length	11 cm
Package 1 Weight	0.113 kg

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Compliant with Exemptions
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	No need of specific recycling operations