


Product data sheet

Characteristics

AK2GD10075

Cable duct - 75 x 100 mm - without cover - grey

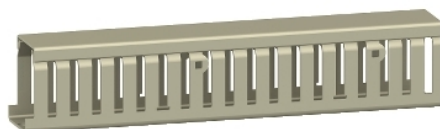

Main

Product or component type	Cable duct
Accessory / separate part category	Cabling accessories
Range compatibility	S3D CRN PLA PLS PLM
Device composition	Without cover
Quantity per set	Set of 8

Complementary

Colour	Grey (RAL 7030)
Fixing mode	By screws Clip-on support
Material	PVC (polyvinyl chloride)
Height	75 mm
Length	2000 mm
Width	100 mm
Product weight	1.2 kg
Total number of wires	550

Environment

Ambient air temperature for operation	-5...60 °C
Flame retardance	VO conforming to UL 94
Fire resistance	960 °C conforming to IEC 60695-2-1/1
Standards	DIN 43659 VDE 0506 VDE 0660

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	1.243 kg
Package 1 Height	7 cm
Package 1 width	10 cm
Package 1 Length	200 cm
Unit Type of Package 2	BB1
Number of Units in Package 2	8
Package 2 Weight	10.391 kg
Package 2 Height	14 cm
Package 2 width	20.5 cm
Package 2 Length	200 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------