


## Product data sheet

### Characteristics

# AK2GD2550

## Cable duct - 50 x 25 mm - without cover - grey

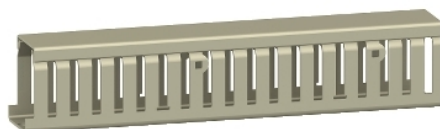

### Main

|                                    |                                 |
|------------------------------------|---------------------------------|
| Product or component type          | Cable duct                      |
| Accessory / separate part category | Cabling accessories             |
| Range compatibility                | S3D<br>CRN<br>PLA<br>PLS<br>PLM |
| Device composition                 | Without cover                   |
| Quantity per set                   | Set of 8                        |

### Complementary

|                       |                              |
|-----------------------|------------------------------|
| Colour                | Grey (RAL 7030)              |
| Fixing mode           | By screws<br>Clip-on support |
| Material              | PVC (polyvinyl chloride)     |
| Height                | 50 mm                        |
| Length                | 2000 mm                      |
| Width                 | 25 mm                        |
| Net weight            | 0.46 kg                      |
| Total number of wires | 65                           |



### Environment

|                                       |                                      |
|---------------------------------------|--------------------------------------|
| Ambient air temperature for operation | -5...60 °C                           |
| Flame retardance                      | V-0 conforming to UL 94              |
| Fire resistance                       | 960 °C conforming to IEC 60695-2-1/1 |
| Standards                             | DIN 43659<br>VDE 0506<br>VDE 0660    |

### Packing Units

|                  |           |
|------------------|-----------|
| Package 1 Weight | 0.425 kg  |
| Package 1 Height | 1.000 dm  |
| Package 1 width  | 0.600 dm  |
| Package 1 Length | 20.000 dm |

### Offer Sustainability

|                            |  |
|----------------------------|--|
| Sustainable offer status   | Green Premium product  |
| REACH free of SVHC         | Yes  |
| EU RoHS Directive          | Pro-active compliance (Product out of EU RoHS legal scope)  <a href="#">EU RoHS Declaration</a> |
| Toxic heavy metal free     | Yes  |
| Mercury free               | Yes  |
| RoHS exemption information |  Yes  |

---

|                          |   |
|--------------------------|---|
| China RoHS Regulation    | <a href="#">China RoHS Declaration</a>        |
| Environmental Disclosure | <a href="#">Product Environmental Profile</a> |

---

### Contractual warranty

---

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

---