


Product data sheet

Characteristics

AK2GD5075

Cable duct - 75 x 50 mm - without cover - grey

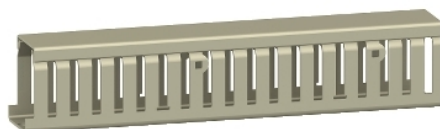

Main

Product or component type	Cable duct
Accessory / separate part category	Cabling accessories
Range compatibility	S3D CRN PLA PLS PLM
Device composition	Without cover
Quantity per set	Set of 8

Complementary

Colour	Grey (RAL 7030)
Fixing mode	By screws Clip-on support
Material	PVC (polyvinyl chloride)
Height	75 mm
Length	2000 mm
Width	50 mm
Net weight	0.88 kg
Total number of wires	240

Environment

Ambient air temperature for operation	-5...60 °C
Flame retardance	VO conforming to UL 94
Fire resistance	960 °C conforming to IEC 60695-2-1/1
Standards	DIN 43659 VDE 0660 VDE 0506

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	852 g
Package 1 Height	11 cm
Package 1 width	14.5 cm
Package 1 Length	200 cm
Unit Type of Package 2	CAR
Number of Units in Package 2	8
Package 2 Weight	7.3 kg
Package 2 Height	11 cm
Package 2 width	14.5 cm
Package 2 Length	200 cm
Unit Type of Package 3	PAL
Number of Units in Package 3	512

Package 3 Weight	479 kg
Package 3 Height	135 cm
Package 3 width	88 cm
Package 3 Length	200 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------