


## Product data sheet

### Characteristics

## BP366N

Max 4 Link Bars, Strip Connectors, 100A,  
Heavy Duty, 12 Terminal

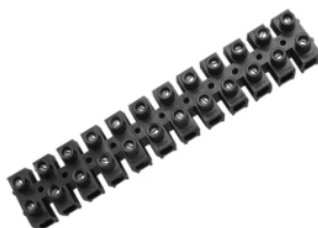

### Main

Product brand	Clipsal
Range of product	Blue Point

### Complementary

Cable cross section	35 mm <sup>2</sup> fine stranded without cable end sleeve
[In] rated current	100 A
Rated voltage	750 V AC
Number of poles	12
Mounting support	Panel
Width	46 mm grid pattern:
Minimum mounting height	39 mm
Length	264 mm

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.9 cm
Package 1 Width	4.6 cm
Package 1 Length	26.2 cm
Package 1 Weight	0.447 kg

### Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 <a href="#">REACH Declaration</a>
EU RoHS Directive	Compliant with Exemptions
Mercury free	Yes
China RoHS Regulation	 <a href="#">China RoHS Declaration</a>
RoHS exemption information	 Yes
Environmental Disclosure	 <a href="#">Product Environmental Profile</a>
Circularity Profile	No need of specific recycling operations