


Product data sheet

Characteristics

BP526P

Max 4 Link Bars, Strip Connectors, 5A, Nylon
Micro, 12 Terminal

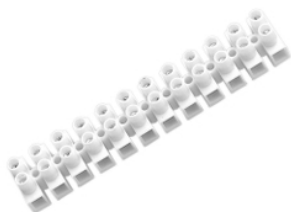

Main

Product brand	Clipsal
Range of product	Blue Point

Complementary

Cable cross section	4 mm ² fine stranded without cable end sleeve
[In] rated current	5 A
Connector type	1 screw terminals 2 screw terminals
Number of poles	12
Mounting support	Panel
Material	Nylon: insulation
Width	16 mm grid pattern:
Minimum mounting height	13 mm
Length	97 mm

Environment

Ambient air temperature for operation	120 °C
Standards	CS/840/N

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	0.029 kg

Offer Sustainability

Sustainable offer status	Green Premium product
RECh Regulation	RECh Declaration
RECh free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile