


## Product data sheet

### Characteristics

# BP535P

## CONNECTOR STRIP 30A

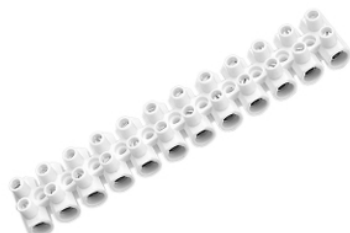

### Main

Product brand	Clipsal
Range of product	Blue Point

### Complementary

Cable cross section	16 mm <sup>2</sup> fine stranded without cable end sleeve
[In] rated current	30 A
Connector type	1 screw terminals 2 screw terminals
Number of poles	12
Mounting support	Panel
Material	Nylon: insulation
Width	28 mm grid pattern:
Minimum mounting height	21 mm
Length	180 mm




### Environment

Ambient air temperature for operation	120 °C
Standards	CS/840/N

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	114.0 g
Package 1 Height	3.0 cm
Package 1 width	2.5 cm
Package 1 Length	17.5 cm

### Offer Sustainability

EU RoHS Directive	Compliant  <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	 Yes
China RoHS Regulation	 <a href="#">China RoHS Declaration</a>