


Product data sheet

Characteristics

BP543

Max 4 Link Bars, Strip Connectors, 15A, Plastic
Medium Duty, 12 Terminal Available Bk Or Tr

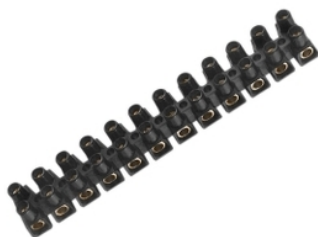

Main

Product brand	Clipsal
Range of product	Blue Point

Complementary

Cable cross section	6 mm ² fine stranded without cable end sleeve
[In] rated current	15 A
Connector type	1 screw terminals 2 screw terminals
Number of poles	12
Mounting support	Panel
Material	Flameproof high-impact polystyrene: insulation
Width	23 mm grid pattern:
Minimum mounting height	19 mm
Length	133 mm

Environment

Ambient air temperature for operation	100 °C
Standards	CS/840/N

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.0 cm
Package 1 Width	2.3 cm
Package 1 Length	14.0 cm
Package 1 Weight	55.0 g

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration

RoHS exemption information

 [Yes](#)

Environmental Disclosure

 [Product Environmental Profile](#)
