


Product data sheet

Characteristics

BP543P

CONNECTOR STRIP 15A 12 WAY

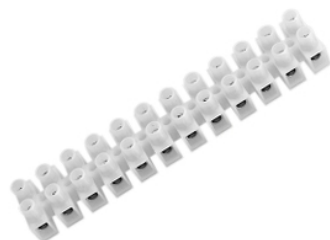

Main

Product brand	Clipsal
Range of product	Blue Point

Complementary

Cable cross section	6 mm ² fine stranded without cable end sleeve
[In] rated current	15 A
Connector type	1 screw terminals 2 screw terminals
Number of poles	12
Mounting support	Panel
Material	Nylon: insulation
Width	23 mm grid pattern:
Minimum mounting height	19 mm
Length	137 mm



Environment

Ambient air temperature for operation	120 °C
Standards	CS/840/N

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	58 g
Package 1 Height	23 mm
Package 1 width	21 mm
Package 1 Length	137 mm

Offer Sustainability

EU RoHS Directive	Compliant  EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	 Yes
China RoHS Regulation	 China RoHS Declaration