


Product data sheet

Characteristics

CEF40N-WE

Exhaust fan, Airflow, ceiling ducted, white

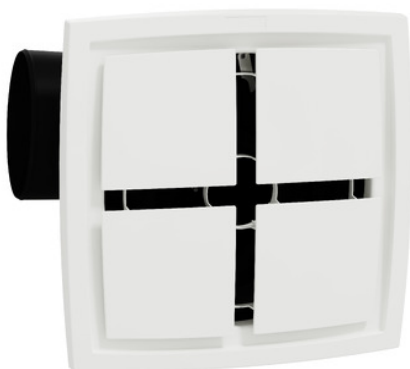

Main

Range of product	Airflow
Range	Airflow
Product brand	Clipsal
Product or component type	Exhaust fan
Product destination	Ceiling fitting
Main colour tint	White
Colour tint	White

Complementary

Provided equipment	Fan 354 mm 354 mm 279 mm
[Ue] rated operational voltage	230 V AC 50 Hz
Material	ABS (acrylonitrile butadiene-styrene)
Air flow	290 m3/h
Power consumption in W	35 W
[In] rated current	0.15 A full load
Plug & lead length	850 mm
Cut-out dimensions	287 mm diameter
Depth	212 mm
Air discharge option	Ducted
Motor type	Ball bearing
Noise level	44 dB
Fan type	Centrifugal

Environment

IP degree of protection	IPx4
-------------------------	------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	30 cm
Package 1 Width	36.2 cm
Package 1 Length	36.2 cm
Package 1 Weight	3.503 kg
Unit Type of Package 2	PAL
Number of Units in Package 2	27
Package 2 Height	111.5 cm
Package 2 Width	113 cm
Package 2 Length	113 cm
Package 2 Weight	120 kg

Offer Sustainability

REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant with Exemptions
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations
Halogen content performance	Halogen free plastic parts product

Contractual warranty

Warranty	3 Years
----------	---------