

## Product data sheet

### Characteristics

# GV2APN01

Extended rotary handle kit, TeSys Deca, IP54, black handle, with trip indication, for GV2L-GV2P



### Main

Range	TeSys TeSys Deca
Device short name	GV2AP
Product or component type	Rotary handle kit
Accessory / separate part category	Control accessory
Handle colour	Black
Handle front plate colour	Grey

### Complementary

Product compatibility	GV2P GV2L
Rotary handle padlocking	Padlock in OFF position Padlock in ON position
Rotary handle mounting style	Extended
Locking options description	1 to 3 padlocks
Back/door distance	140...250 mm
Product weight	0.2 kg

### Environment

IP degree of protection	IP54
-------------------------	------

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	362 g
Package 1 Height	6.5 cm
Package 1 width	9 cm
Package 1 Length	37 cm
Unit Type of Package 2	S03
Number of Units in Package 2	12
Package 2 Weight	4.728 kg
Package 2 Height	30 cm
Package 2 width	30 cm
Package 2 Length	40 cm
Unit Type of Package 3	P06
Number of Units in Package 3	96
Package 3 Weight	50.492 kg
Package 3 Height	77 cm

Package 3 width	60 cm
Package 3 Length	80 cm

### Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins


### Contractual warranty

Warranty	18 months
----------	-----------


---

Mounting of External Operator GV2APN01, GV2APN02 or GV2APN04 for Motor Circuit Breakers GV2L

---

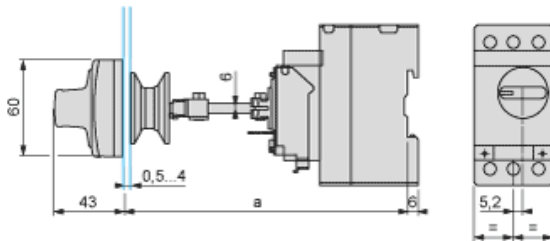

Door cut-out

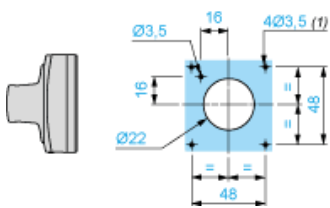

(1) For IP65 only.