


## Product data sheet

### Characteristics

# GV2G245

Linergy FT - Comb busbar - 63 A - 2 tap-offs - 45 mm pitch

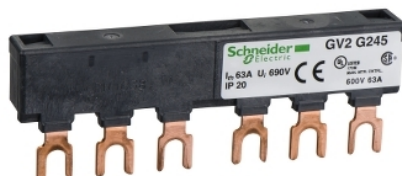

### Main

Range	Linergy
Product name	FT
Device short name	GV2G
Product or component type	Comb busbar
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys D TeSys GV2 TeSys K TeSys U
Number of tap-offs	2
[I <sub>th</sub> ] conventional free air thermal current	63 A
Connection pitch	45 mm

### Complementary

Mounting location	On terminal
[U <sub>i</sub> ] rated insulation voltage	690 V
Length	89 mm
Product weight	0.036 kg

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	38 g
Package 1 Height	2 cm
Package 1 width	4 cm
Package 1 Length	9.5 cm
Unit Type of Package 2	S01
Number of Units in Package 2	100
Package 2 Weight	3.787 kg
Package 2 Height	15 cm
Package 2 width	15 cm
Package 2 Length	40 cm
Unit Type of Package 3	P06
Number of Units in Package 3	3200
Package 3 Weight	130.9 kg
Package 3 Height	77 cm
Package 3 width	60 cm
Package 3 Length	80 cm

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.


## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>


## Contractual warranty

Warranty	18 months
----------	-----------

Sets of Busbars GV2G... with Terminal Block GV1G09

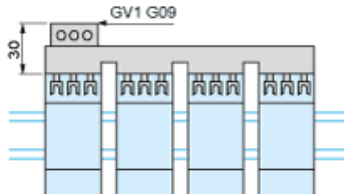

Sets of Busbars GV2G245, GV2G254, GV2GR272

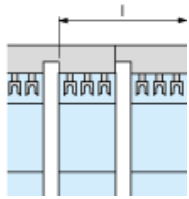

	l
GV2G245 (2 x 45 mm)	89
GV2G254 (2 x 54 mm)	98
GV2G272 (2 x 72 mm)	116