

## Product data sheet

### Characteristics

# GV2G254

Linery, Linery FT, Comb busbar, 63 A, 2 tap-offs, 54 mm pitch



### Main

Range	Linery
Product name	FT
Device short name	GV2G
Product or component type	Comb busbar
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys GV2 TeSys K TeSys U TeSys Deca
Number of tap-offs	2
[I <sub>th</sub> ] conventional free air thermal current	63 A
Connection pitch	54 mm

### Complementary

Mounting location	On terminal
[U <sub>i</sub> ] rated insulation voltage	690 V
Length	98 mm
Net weight	0.038 kg

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	1 cm
Package 1 Width	8 cm
Package 1 Length	14 cm
Package 1 Weight	40 g
Unit Type of Package 2	S01
Number of Units in Package 2	80
Package 2 Height	15 cm
Package 2 Width	15 cm
Package 2 Length	40 cm
Package 2 Weight	3.285 kg
Unit Type of Package 3	P06
Number of Units in Package 3	2560
Package 3 Height	77 cm
Package 3 Width	80 cm
Package 3 Length	60 cm
Package 3 Weight	118.1 kg


## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	<a href="#">End Of Life Information</a>


## Contractual warranty

Warranty	18 months
----------	-----------

Sets of Busbars GV2G... with Terminal Block GV1G09

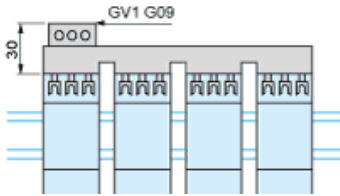

Sets of Busbars GV2G245, GV2G254, GV2GR272

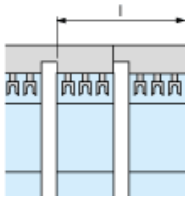

	l
GV2G245 (2 x 45 mm)	89
GV2G254 (2 x 54 mm)	98
GV2G272 (2 x 72 mm)	116