


## Product data sheet

### Characteristics

# GV2G445

Linery FT - Comb busbar - 63 A - 4 tap-offs - 45 mm pitch

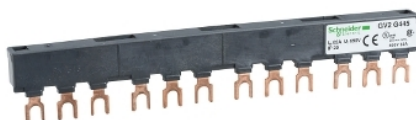

### Main

Range	Linery
Product name	FT
Device short name	GV2G
Product or component type	Comb busbar
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys D TeSys GV2 TeSys K TeSys U
Number of tap-offs	4
[I <sub>th</sub> ] conventional free air thermal current	63 A
Connection pitch	45 mm



### Complementary

Mounting location	On terminal
[U <sub>i</sub> ] rated insulation voltage	690 V
Length	179 mm
Net weight	0.077 kg

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	78 g
Package 1 Height	1 cm
Package 1 width	3.5 cm
Package 1 Length	18 cm
Unit Type of Package 2	S01
Number of Units in Package 2	60
Package 2 Weight	4.885 kg
Package 2 Height	15 cm
Package 2 width	15 cm
Package 2 Length	40 cm

### Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 <a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant  <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes

---

RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>

---


### Contractual warranty

---

Warranty	18 months
----------	-----------

---

Sets of Busbars GV2G445, GV2G454, GV2G472, with Terminal Block GV2G05

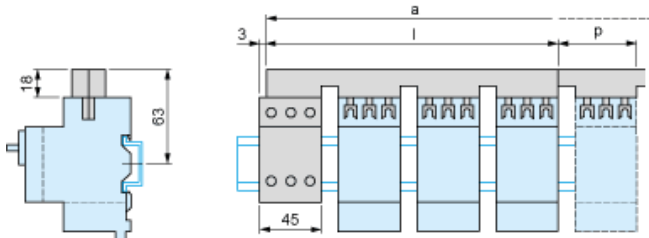

	l	p
GV2G445 (4 x 45 mm)	179	45
GV2G454 (4 x 54 mm)	206	54
GV2G472 (4 x 72 mm)	260	72

Number of tap-offs	a			
	5	6	7	8
GV2G445	224	269	314	359
GV2G454	260	314	368	422
GV2G472	332	404	476	548