 


## Product data sheet

### Characteristics

# GV2G454

## Linergy FT - Comb busbar - 63 A - 4 tap-offs - 54 mm pitch



### Main

|  |  |
|--|--|
| Range  | Linergy                                    |
| Product name   | FT   |
| Device short name  | GV2G                                       |
| Product or component type                                | Comb busbar                                |
| Accessory / separate part category                       | Connection accessory                       |
| Poles description  | 3P   |
| Range compatibility                                      | TeSys D<br>TeSys GV2<br>TeSys K<br>TeSys U |
| Number of tap-offs                                       | 4  |
| [I <sub>th</sub> ] conventional free air thermal current | 63 A                                       |
| Connection pitch   | 54 mm                                      |

### Complementary

|  |             |
|--|-------------|
| Mounting location                          | On terminal |
| [U <sub>i</sub> ] rated insulation voltage | 690 V       |
| Length                                     | 206 mm      |
| Net weight                                 | 0.085 kg    |


### Offer Sustainability

|                            |   |
|----------------------------|---|
| Sustainable offer status   | Green Premium product                         |
| REACH Regulation           | <a href="#">REACH Declaration</a>             |
| REACH free of SVHC         | Yes   |
| EU RoHS Directive          | Compliant <a href="#">EU RoHS Declaration</a> |
| Toxic heavy metal free     | Yes   |
| Mercury free               | Yes   |
| RoHS exemption information | <a href="#">Yes</a>                           |
| China RoHS Regulation      | <a href="#">China RoHS Declaration</a>        |
| Environmental Disclosure   | <a href="#">Product Environmental Profile</a> |

### Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Sets of Busbars GV2G445, GV2G454, GV2G472, with Terminal Block GV2G05

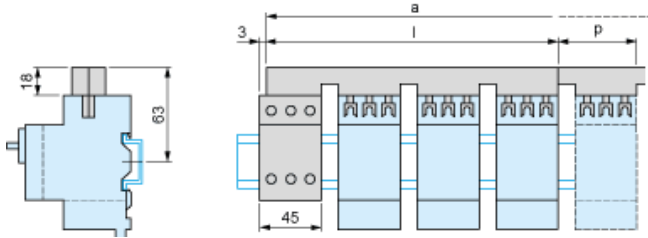

|                     | l   | p  |
|---------------------|-----|----|
| GV2G445 (4 x 45 mm) | 179 | 45 |
| GV2G454 (4 x 54 mm) | 206 | 54 |
| GV2G472 (4 x 72 mm) | 260 | 72 |

| Number of tap-offs | a   |     |     |     |
|--------------------|-----|-----|-----|-----|
|                    | 5   | 6   | 7   | 8   |
| GV2G445            | 224 | 269 | 314 | 359 |
| GV2G454            | 260 | 314 | 368 | 422 |
| GV2G472            | 332 | 404 | 476 | 548 |