


## Product data sheet

### Characteristics

# INS12203

OptiLine 50 - bend - 100 x 63 mm - PC/ABS - white

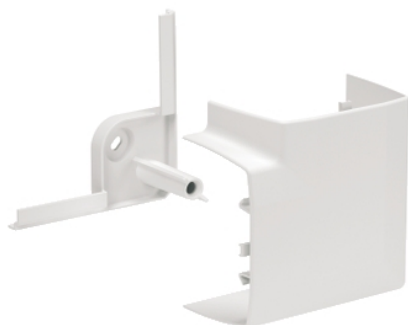

#### Main

Product or component type	Bend
Quantity per set	1 piece
Colour tint	White (RAL 9010)

#### Complementary

Trunking dimension	100 x 63 mm
Trunking material	Aluminium Plastic
Fixing mode	Screw-fixed
Material	PC/ABS
Length	122 mm
Height	122 mm
Width	63 mm



#### Environment

Ambient air temperature for operation	-25...60 °C
IP degree of protection	IP40
IK degree of protection	IK07

#### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	116 g
Package 1 Height	7.6 cm
Package 1 width	18 cm
Package 1 Length	18.1 cm

#### Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes

RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>

### Contractual warranty

Warranty	18 months
----------	-----------