


Product data sheet

Characteristics

INS12400

OptiLine 50 - installation trunking - 140 x 63 mm - plastic - white - 2.5 m

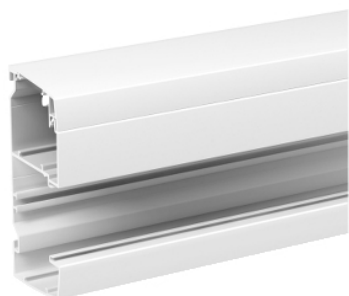

Main

Range of product	OptiLine 50
Product or component type	Installation trunking
Colour tint	White (RAL 9010)
Quantity per set	10 m

Complementary

Compartment partitioning	2 compartments
Trunking dimension	140 x 63 mm
Trunking material	Plastic
Front opening size	50 mm
Fixing mode	By brackets Screw-fixed
Material	PC/ABS
Length	2500 mm
Height	140 mm
Width	63 mm

Environment

Ambient air temperature for operation	-25...60 °C
IP degree of protection	IP40
IK degree of protection	IK07

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	14 cm
Package 1 Width	6.3 cm
Package 1 Length	100 cm
Package 1 Weight	2764 kg

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------