


Product data sheet

Characteristics

INS43402

OptiLine, OptiLine 50 - pole - free-standing - one sided - empty - anodized - Australian

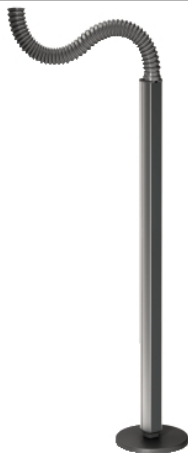

Main

| | |
|---------------------------|--------------------------|
| Range | OptiLine |
| Product name | OptiLine 50 |
| Product type | Pole |
| Type of pole | One-sided |
| Configuration | Empty |
| Additional information | Flexible conduit 2000 mm |
| Colour | Natural |
| Quantity package 1 / unit | Set of 1 |

Complementary

| | |
|--------------------------|--|
| Pole/post surface finish | Anodized |
| Fixing mode | Free-standing |
| Device composition | Front cover Floor fixing Stop end Earth terminal Earth clamp Mounting instruction Flexible conduit 2000 mm Strain relief Earth cable |
| Product material | Aluminium conforming to EN-AW-6063 PC/ABS conforming to UL 94 HB |
| Marking | CE |
| Height | 2150 mm |
| Width | 68 mm |

Environment

| | |
|-------------------------|---|
| Standards | EN 50085-1:2005 IEC 1084-2-4 EN 60598-2-2 73/23/EEC 93/68/EEC |
| Directives | 2014/35/EU - low voltage directive |
| Operating temperature | -15...60 °C |
| IP degree of protection | IP30 |

Packing Units

| | |
|------------------------------|---------|
| Unit Type of Package 1 | PCE |
| Number of Units in Package 1 | 1 |
| Package 1 Height | 6.8 cm |
| Package 1 Width | 8.9 cm |
| Package 1 Length | 215 cm |
| Package 1 Weight | 5.91 kg |

Offer Sustainability

EU RoHS Directive

Not applicable, out of EU RoHS legal scope