


Product data sheet

Characteristics

ISM20521

OptiLine 70 - pole - free-standing - two-sided - natural - 2420 mm

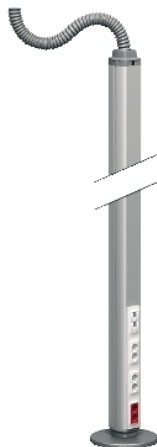

Main

| | |
|-----------------------------|---------------|
| Range | OptiLine |
| Product name | OptiLine 70 |
| Cabling installation system | Pole |
| Product type | Pole |
| Type of pole | Two-sided |
| Pole/post surface finish | Anodized |
| Pole fixing mode | Free-standing |

Complementary

| | |
|---------------------------|--------------------|
| Colour | Natural |
| Front opening size | 70 mm |
| Material | Aluminium anodized |
| Quantity package 1 / unit | Set of 1 |
| Height | 2420 mm |
| Depth | 118 mm |
| Width | 120 mm |

Environment

| | |
|-------------------------|--|
| Standards | 73/23/EEC 93/68/EEC IEC 1084-2-4 SS 424 10 32 EN-AW-6063 |
| Operating temperature | -25...60 °C |
| IP degree of protection | IP40 |

Packing Units

| | |
|------------------------------|------------|
| Unit Type of Package 1 | PCE |
| Number of Units in Package 1 | 1 |
| Package 1 Weight | 9.596 kg |
| Package 1 Height | 11.8 cm |
| Package 1 width | 12 cm |
| Package 1 Length | 242 cm |
| Unit Type of Package 2 | PAL |
| Number of Units in Package 2 | 16 |
| Package 2 Weight | 173.536 kg |
| Package 2 Height | 92 cm |
| Package 2 width | 255 cm |
| Package 2 Length | 120 cm |

Offer Sustainability

| | |
|--------------------------|--|
| EU RoHS Directive | Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration |
| Environmental Disclosure | Product Environmental Profile |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|