


Product data sheet

Characteristics

ISM20813

OptiLine 45 OptiLine 70 - ceiling fixing - white

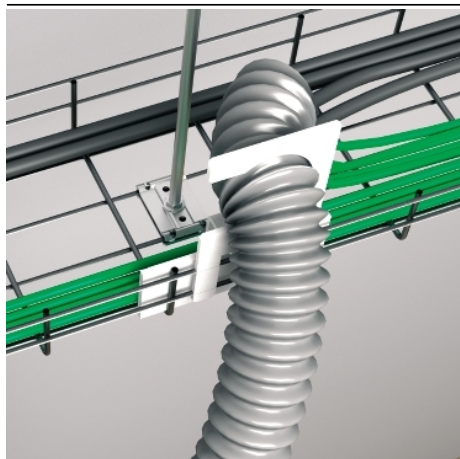

Main

Cabling installation system	Service box Pole
Product or component type	Ceiling fixing

Complementary

Type of pole	Two-sided Two installation boxes One installation box One-sided
Type of service box	Service box kit
Device presentation	Empty
Colour tint	White (RAL 9010)
Quantity per set	Set of 1
Product compatibility	Altira wiring device Unica wiring device
Pole/post surface finish	Anodized Powder coated
Pole fixing mode	Free-standing
Fixing mode	By screws
Material	Steel powder coated
Length	70 mm
Height	100 mm
Width	15 mm
Market segment	Small commercial Residential

Environment

Ambient air temperature for operation	-25...60 °C
IP degree of protection	IP30

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	147 g
Package 1 Height	3.8 cm
Package 1 width	7.1 cm
Package 1 Length	11 cm
Unit Type of Package 2	S03

Number of Units in Package 2	50
Package 2 Weight	7.837 kg
Package 2 Height	30 cm
Package 2 width	30 cm
Package 2 Length	40 cm

Offer Sustainability

EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------