


## Product data sheet

### Characteristics

# ISM20817

## OptiLine 45 OptiLine 70 - floor feeder - grey

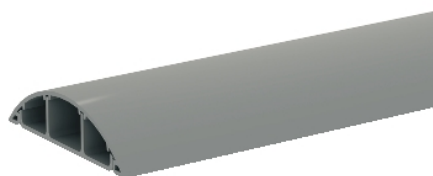

### Main

Cabling installation system	Pole Post
Product or component type	Floor feeder

### Complementary

Type of pole	One-sided Two installation boxes Two-sided One installation box
Type of post	One-sided Two-sided
Colour tint	Grey (RAL 7030)
Quantity per set	28 m
Pole/post surface finish	Anodized Powder coated
Pole fixing mode	Tension-mounted
Fixing mode	By screws
Material	PVC (polyvinyl chloride)
Length	2000 mm
Height	18 mm
Width	75 mm
Market segment	Small commercial Residential

### Environment

Standards	EN 50085-1:2005 NF C 68-102
Ambient air temperature for operation	-25...60 °C
IP degree of protection	IP30

### Offer Sustainability

EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	 Yes
China RoHS Regulation	 <a href="#">China RoHS Declaration</a>
Environmental Disclosure	 <a href="#">Product Environmental Profile</a>

## Contractual warranty

---

Warranty

18 months

---