


## Product data sheet

### Characteristics

# KBA25ABG4

Canalis - feed unit for KBA - 25 A - left mounting

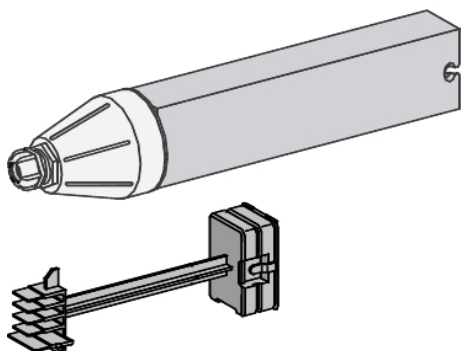

### Main

Range of product	Canalis
Product or component type	Feed unit
BAR MATERIAL	Aluminium
Product compatibility	KBA
[Ie] rated operational current	25 A
Mounting location	Left

### Complementary

Protection type	Without protection
[Ue] rated operational voltage	230...400 V
Connections - terminals	Terminal block - screw clamp connector for 4 mm <sup>2</sup>
Control type	Without
Number of circuits	1
Provided equipment	End cover
Mounting mode	By screws
Mounting support	Busbar
Standards	IEC 60439-2 IEC 61439-6
Width	273 mm
Depth	57 mm
Height	57 mm

### Environment

IP degree of protection	IP55 conforming to IEC 60529
-------------------------	------------------------------

### Packing Units

Package 1 Weight	0.200 kg
Package 1 Height	0.800 dm
Package 1 width	0.800 dm
Package 1 Length	2.700 dm

### Offer Sustainability

Sustainable offer status	Green Premium product
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>

## Contractual warranty

---

Warranty

18 months

---