


Product data sheet

Characteristics

L5504RVF20

RELAY C-BUS 4 CH 20A DIN LEARN

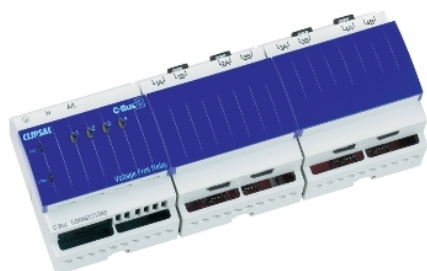

Main

Range	C-Bus
Product brand	Clipsal

Complementary

[Us] rated supply voltage	15...36 V DC
Device composition	Socket-outlet
Connector type	Screw terminals
Width	215 mm
Height	85 mm
Depth	65 mm

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	631.0 g
Package 1 Height	9.5 cm
Package 1 width	10.5 cm
Package 1 Length	22 cm
Unit Type of Package 2	P12
Number of Units in Package 2	180
Package 2 Weight	130.89 kg
Package 2 Height	95 cm
Package 2 width	80 cm
Package 2 Length	120 cm
Unit Type of Package 3	CAR
Number of Units in Package 3	6
Package 3 Weight	4.063 kg
Package 3 Height	24.5 cm
Package 3 width	21 cm
Package 3 Length	34 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins