


Product data sheet

Characteristics

LA4DE3E

TeSys D - suppressor module - varistor - 24...48 V DC

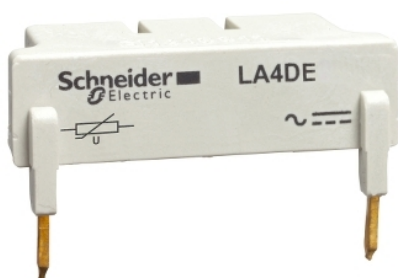

Main

| | |
|---------------------------|--|
| Range | TeSys |
| Device short name | LA4D |
| Product or component type | Suppressor module |
| Product compatibility | 4P LC1D40008...D80008 3P LC1D80...D95 4P LP1D80004 |

Complementary

| | |
|------------------------------|--------------------------|
| Mounting location | Top |
| Mounting mode | By screws |
| Suppressor technology | Varistor (peak limiting) |
| [Uc] control circuit voltage | 24...48 V DC |
| Maximum peak voltage | 2 Uc |
| Net weight | 0.018 kg |

Environment

| | |
|---------------------------------------|-------------|
| Ambient air temperature for operation | -25...55 °C |
| Ambient air temperature for storage | -40...80 °C |

Packing Units

| | |
|------------------------------|----------|
| Unit Type of Package 1 | PCE |
| Number of Units in Package 1 | 1 |
| Package 1 Weight | 16 g |
| Package 1 Height | 2.7 cm |
| Package 1 width | 4 cm |
| Package 1 Length | 5 cm |
| Unit Type of Package 2 | S01 |
| Number of Units in Package 2 | 78 |
| Package 2 Weight | 1.455 kg |
| Package 2 Height | 15 cm |
| Package 2 width | 15 cm |
| Package 2 Length | 40 cm |

Offer Sustainability

| | |
|----------------------------|---|
| Sustainable offer status | Green Premium product |
| REACH free of SVHC | Yes |
| EU RoHS Directive | Compliant EU RoHS Declaration |
| Toxic heavy metal free | Yes |
| Mercury free | Yes |
| RoHS exemption information | Yes |
| China RoHS Regulation | China RoHS Declaration |
| Environmental Disclosure | Product Environmental Profile |
| WEEE | The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|