


## Product data sheet

### Characteristics

# LA4DE3U

## Suppressor Module, TeSys D, varistor, 110...250 V DC

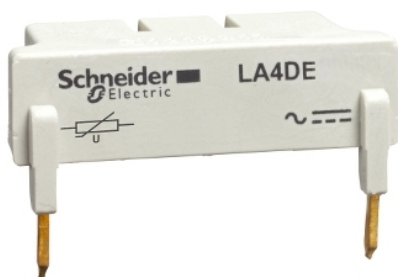

### Main

Range	TeSys
Device short name	LA4D
Product or component type	Suppressor module
Product compatibility	4P LP1D80 3P LC1D80...D95

### Complementary

Mounting location	Top
Mounting mode	By screws
Suppressor technology	Varistor (peak limiting)
[Uc] control circuit voltage	110...250 V DC
Maximum peak voltage	2 Uc
Net weight	0.018 kg

### Environment

Standards	IEC 60947-5-1 EN 60947-5-1 CSA C22.2 No 60947-5-1 UL 60947-5-1 GB/T 14048.5
Product certifications	UL[RETURN]CSA
IP degree of protection	IP2X conforming to IEC 60529
Ambient air temperature for operation	-25...55 °C
Ambient air temperature for storage	-40...80 °C

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.9 cm
Package 1 Width	4.3 cm
Package 1 Length	5.2 cm
Package 1 Weight	16 g
Unit Type of Package 2	S01
Number of Units in Package 2	32
Package 2 Height	15 cm
Package 2 Width	15 cm
Package 2 Length	40 cm
Package 2 Weight	768 g

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	No need of specific recycling operations
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins

## Contractual warranty

Warranty	18 months
----------	-----------