


## Product data sheet

### Characteristics

# MX9B112N

Clipsal MAX9, MAXBAR Top Feed, 1P+N, 12 Modules, 100 A with N Block and Accessories

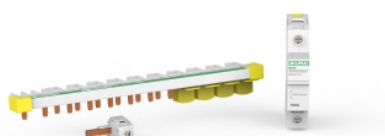

### Main

|                               |             |
|-------------------------------|-------------|
| Product brand                 | Clipsal     |
| Range                         | MAX9        |
| Product or component type     | Comb busbar |
| Total number of 18 mm modules | 12          |

### Complementary

|  |   |
|--|---|
| Number of ways                         | Outgoer: 10 ways N + L<br>Incomer: 2 ways N + L           |
| Poles configuration                    | Outgoer: 1P + N   |
| Connection pitch                       | Incomer: 18 mm<br>Outgoer: 9 mm                           |
| Insulation                             | Insulated   |
| Device presentation                    | Cuttable  |
| Provided components                    | 1 connector<br>4 tooth covers<br>1 neutral terminal block |
| [Ie] rated operational current         | 100 A   |
| [Ue] rated operational voltage         | 230 V AC  |
| [Ui] rated insulation voltage          | 500 V   |
| [Uimp] rated impulse withstand voltage | 4 kV  |
| Mounting mode                          | Horizontal  |
| Mounting location                      | Top   |
| Colour                                 | White (RAL 9003)  |

### Environment





|                 |                               |
|-----------------|-------------------------------|
| Standards       | AS/NZS 61439-3<br>AS/NZS 3000 |
| Fire resistance | 960 °C                        |

### Packing Units

|                              |         |
|------------------------------|---------|
| Unit Type of Package 1       | PCE     |
| Number of Units in Package 1 | 1       |
| Package 1 Height             | 4.0 cm  |
| Package 1 Width              | 30.0 cm |
| Package 1 Length             | 12.5 cm |
| Package 1 Weight             | 180.0 g |
| Unit Type of Package 2       | CAR     |
| Number of Units in Package 2 | 12      |
| Package 2 Height             | 26.2 cm |

|                  |         |
|------------------|---------|
| Package 2 Width  | 27.3 cm |
| Package 2 Length | 33.4 cm |
| Package 2 Weight | 2.2 kg  |

## Offer Sustainability

|                            |   |
|----------------------------|---|
| REACH Regulation           |  <a href="#">REACH Declaration</a>             |
| EU RoHS Directive          | Compliant  <a href="#">EU RoHS Declaration</a> |
| Toxic heavy metal free     | Yes   |
| Mercury free               | Yes   |
| China RoHS Regulation      |  <a href="#">China RoHS Declaration</a>        |
| RoHS exemption information |  <a href="#">Yes</a>                           |
| Circularity Profile        | No need of specific recycling operations  |

## Contractual warranty

|          |        |
|----------|--------|
| Warranty | 7-year |
|----------|--------|