


## Product data sheet

### Characteristics

# MX9B115N

## Clipsal MAX9, MAXBAR Top Feed, 1P+N, 15 Modules, 100 A with N Block and Accessories

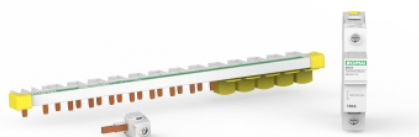

### Main

Product brand	Clipsal
Range	MAX9
Product or component type	Comb busbar
Total number of 18 mm modules	15

### Complementary

Number of ways	Outgoer: 13 ways N + L Incomer: 2 ways N + L
Poles configuration	Outgoer: 1P + N
Connection pitch	Incomer: 18 mm Outgoer: 9 mm
Insulation	Insulated
Device presentation	Cuttable
Provided components	1 connector 5 tooth covers 1 neutral terminal block
[Ie] rated operational current	100 A
[Ue] rated operational voltage	230 V AC
[Ui] rated insulation voltage	500 V
[Uimp] rated impulse withstand voltage	4 kV
Mounting mode	Horizontal
Mounting location	Top
Colour	White (RAL 9003)

### Environment

Standards	AS/NZS 61439-3 AS/NZS 3000
Fire resistance	960 °C

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4.0 cm
Package 1 Width	30.0 cm
Package 1 Length	12.5 cm
Package 1 Weight	180.0 g
Unit Type of Package 2	CAR
Number of Units in Package 2	12

Package 2 Height	26.2 cm
Package 2 Width	27.3 cm
Package 2 Length	33.4 cm
Package 2 Weight	2.2 kg

### Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>

### Contractual warranty

Warranty	7-year
----------	--------