


Product data sheet

Characteristics

MX9B121N

Clipsal MAX9, MAXBAR Top Feed, 1P+N, 21 Modules, 100 A with N Block and Accessories

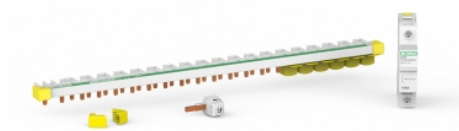

Main

Product brand	Clipsal
Range	MAX9
Product or component type	Comb busbar
Total number of 18 mm modules	21

Complementary

Number of ways	Outgoer: 19 ways N + L Incomer: 2 ways N + L
Poles configuration	Outgoer: 1P + N
Connection pitch	Incomer: 18 mm Outgoer: 9 mm
Insulation	Insulated
Device presentation	Cuttable
Provided components	2 end-pieces 6 tooth covers 1 connector 1 neutral terminal block
[Ie] rated operational current	100 A
[Ue] rated operational voltage	230 V AC
[Ui] rated insulation voltage	500 V
[Uimp] rated impulse withstand voltage	4 kV
Mounting mode	Horizontal
Mounting location	Top
Colour	White (RAL 9003)

Environment

Standards	AS/NZS 61439-3 AS/NZS 3000
Fire resistance	960 °C

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	4.0 cm
Package 1 Width	40.0 cm
Package 1 Length	12.5 cm
Package 1 Weight	310.0 g
Unit Type of Package 2	CAR
Number of Units in Package 2	10

Package 2 Height	26.2 cm
Package 2 Width	27.3 cm
Package 2 Length	33.4 cm
Package 2 Weight	4.0 kg

Offer Sustainability

REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Circularity Profile	No need of specific recycling operations

Contractual warranty

Warranty	7-year
----------	--------