


Product data sheet

Characteristics

NSYTBP19168T

PC box IP66 IK08 RAL7035 Int.H175W150D80
Ext.H193W164D87 Transp.cover H20

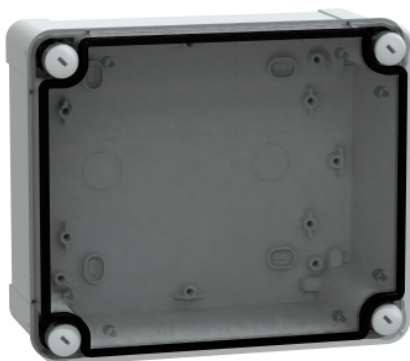

Main

| | |
|---------------------|--|
| Range | Thalassa |
| Product name | Thalassa TBP |
| Device application | Multi-purpose |
| Category | Industrial box |
| Height | 192 mm |
| Width | 164 mm |
| Depth | 87 mm |
| Internal height | 175 mm |
| Internal width | 150 mm |
| Internal depth | 80 mm |
| Enclosure mounting | Wall mounted |
| Device composition | 1 body 1 cover 4 cover screw |
| Body type | One piece moulded |
| Type of front cover | Low transparent cover |
| Cover fixing | Plastic screws |
| Lock type | Captive screw flat outside sealed area |
| Removable parts | Cover by captive screws |

Complementary

| | |
|-----------------------------|---|
| Material | Polycarbonate |
| Colour | Grey (RAL 7035) Transparent |
| Standards | IEC 62208 UL 508 A |
| Product certifications | TÜV UL |
| Electrical insulation class | Class II |
| Mounting location | Outdoor (with canopy or shelter and anticondensation valve) |
| Net weight | 0.46 kg |

Environment

| | |
|-------------------------------------|------------------------------|
| IP degree of protection | IP66 conforming to NEMA 4.4X |
| IK degree of protection | IK08 conforming to IEC 62262 |
| Fire resistance | 960 °C |
| Ambient air temperature for storage | -15...60 °C |
| Operating temperature | -25...80 °C |

The information provided in this documentation contains general descriptions and/or technical characteristics of the products of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

Packing Units

| | |
|------------------------------|---------|
| Unit Type of Package 1 | PCE |
| Number of Units in Package 1 | 1 |
| Package 1 Weight | 460.0 g |
| Package 1 Height | 8.7 cm |
| Package 1 width | 16.4 cm |
| Package 1 Length | 19.3 cm |

Offer Sustainability

| | |
|----------------------------|--|
| Sustainable offer status | Green Premium product |
| REACH Regulation | REACH Declaration |
| REACH free of SVHC | Yes |
| EU RoHS Directive | Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration |
| Toxic heavy metal free | Yes |
| Mercury free | Yes |
| RoHS exemption information | Yes |
| China RoHS Regulation | China RoHS Declaration |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|