


## Product data sheet

### Characteristics

NSYTBP241912H  
 PC box IP66 IK08 RAL7035  
 Int.H225W175D120 Ext.H241W194D127  
 opaque PC cover H40

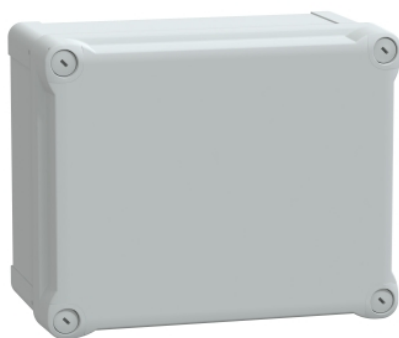

#### Main

Range	Thalassa
Product name	Thalassa TBP
Device application	Multi-purpose
Category	Industrial box
Height	241 mm
Width	194 mm
Depth	127 mm
Internal height	225 mm
Internal width	175 mm
Internal depth	120 mm
Enclosure mounting	Wall mounted
Device composition	1 body 1 cover 4 cover screw
Body type	One piece moulded
Type of front cover	High plain cover
Cover fixing	Plastic screws
Lock type	Captive screw flat outside sealed area
Removable parts	Cover by captive screws

#### Complementary

Material	Polycarbonate
Colour	Grey (RAL 7035)
Standards	UL 508 A IEC 62208
Product certifications	TÜV UL
Electrical insulation class	Class II
Mounting location	Outdoor (with canopy or shelter and anticondensation valve)
Net weight	0.78 kg

#### Environment

IP degree of protection	IP66 conforming to NEMA 4.4X
IK degree of protection	IK08 conforming to IEC 62262
Fire resistance	960 °C
Ambient air temperature for storage	-15...60 °C
Operating temperature	-25...80 °C

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

## Packing Units

Unit Type of Package 1	Db
Number of Units in Package 1	1
Package 1 Height	14 cm
Package 1 Width	20 cm
Package 1 Length	25.5 cm
Package 1 Weight	878 g
Unit Type of Package 2	CAR
Number of Units in Package 2	8
Package 2 Height	40 cm
Package 2 Width	40 cm
Package 2 Length	60 cm
Package 2 Weight	7.32 kg
Unit Type of Package 3	PAM
Number of Units in Package 3	200
Package 3 Height	220 cm
Package 3 Width	100 cm
Package 3 Length	120 cm
Package 3 Weight	203 kg

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	<a href="#">End Of Life Information</a>

## Contractual warranty

Warranty	18 months
----------	-----------