


Product data sheet

Characteristics

NSYTRAP22BL

Linery, Partition Plate, 2PTS 2mm Blue, for
Screw Terminals NSY TRV22,TRV42, T

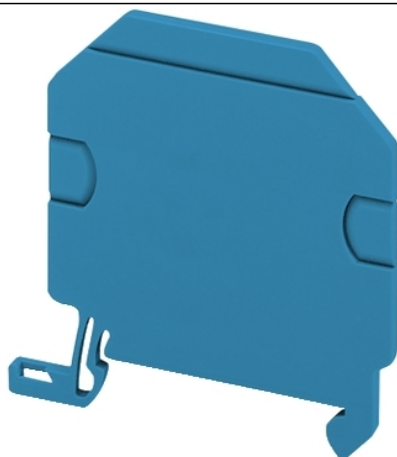

Main

Range	Linery
Product name	Linery TR
Product or component type	Partition
Device short name	TRA
Accessory / separate part category	Insulation accessory
Product compatibility	TRV screw terminal - passthrough terminal block, length = 47.7 mm[RETURN]TRV screw terminal - protective earth terminal block, length = 47.7 mm[RETURN]TRV screw terminal - blade disconnect terminal block, length = 55 mm
Thickness	2 mm

Complementary

Cable cross section	2.5 Mm ² 6 Mm ² 10 Mm ² 4 mm ²
Number of connections	2
Number of measurement input	1 2
Quantity per set	Set of 50
Net weight	4.9 g
Colour	Blue

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	0.5 cm
Package 1 Width	5 cm
Package 1 Length	5.5 cm
Package 1 Weight	4 g
Unit Type of Package 2	BAG
Number of Units in Package 2	50
Package 2 Height	4 cm
Package 2 Width	17 cm
Package 2 Length	17 cm
Package 2 Weight	247 g
Unit Type of Package 3	S01
Number of Units in Package 3	400
Package 3 Height	15 cm
Package 3 Width	15 cm
Package 3 Length	40 cm
Package 3 Weight	2.181 kg

Offer Sustainability

REACH Regulation	 REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes

Contractual warranty

Warranty	18 months
----------	-----------