


## Product data sheet

### Characteristics

# SAU40084183

Acti9, SAU Chassis 3PH 400A, 18mm for iC60 MCB & RCBO, 84 Poles, Top or Bottom Feed

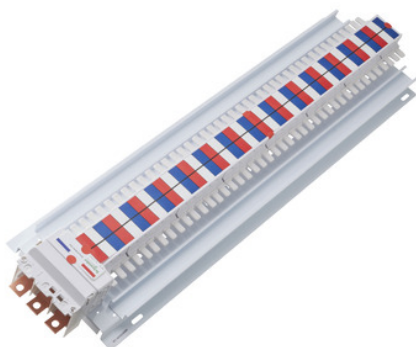

### Main

|                           |              |
|---------------------------|--------------|
| Range                     | Acti9        |
| Product or component type | Chassis      |
| Device application        | Distribution |

### Complementary

|  |  |
|--|--|
| Incomer device                         | Switch disconnecter - 3P<br>MCCB - 3P  |
| Protection device type                 | Miniature circuit breaker (MCB) as outgoer<br>Residual current circuit breaker with overcurrent protection (RCBO) as outgoer |
| Network type                           | AC   |
| [In] rated current                     | 400 A  |
| Number of ways                         | 1 way (incomer) - 3P<br>1 way (outgoer) - 1P or 3P   |
| Rated voltage                          | 415 V 50 Hz  |
| Short-circuit withstand                | 25 kA 0.1 s  |
| [Ui] rated insulation voltage          | 500 V  |
| [Uimp] rated impulse withstand voltage | 6 kV   |
| Number of poles                        | 84   |
| Number of poles                        | 84 x 18 mm   |
| Width                                  | 245 mm   |
| Length                                 | 950 mm   |
| Depth                                  | 95 mm  |
| Net weight                             | 6.96 kg  |
| Busbar pitch                           | 18 mm  |
| Location of connection                 | Top or bottom  |

### Environment

|           |              |
|-----------|--------------|
| Standards | AS/NZS 61439 |
|-----------|--------------|

### Packing Units

|                              |          |
|------------------------------|----------|
| Unit Type of Package 1       | PCE      |
| Number of Units in Package 1 | 1        |
| Package 1 Height             | 9.5 cm   |
| Package 1 Width              | 24.3 cm  |
| Package 1 Length             | 95 cm    |
| Package 1 Weight             | 5.956 kg |

## Offer Sustainability

|                            |  |
|----------------------------|--|
| REACH Regulation           | <a href="#">REACH Declaration</a>                          |
| EU RoHS Directive          | Pro-active compliance (Product out of EU RoHS legal scope) |
| Mercury free               | Yes  |
| China RoHS Regulation      | <a href="#">China RoHS Declaration</a>                     |
| RoHS exemption information | <a href="#">Yes</a>  |