


Product data sheet

Characteristics

SEA9BN18PEV

Acti9, IsoBar B - pan assembly - 18 ways TP + earth + neutral

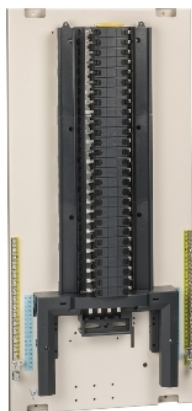

Main

Range	Acti9
Product or component type	Pan assembly
Device application	Distribution

Complementary

Range compatibility	Acti 9 (Acti9 IsoBar B) distribution board
Provided equipment	Grounding bar Mounting plate Neutral bar DIN rail
[In] rated current	250 A
Incomer device options	4P switch disconnecter 4P terminal block 3P + N RCCB 3P + N MCCB 4P contactor
Protection device options at outgoer	Residual current circuit breaker with overcurrent protection (RCBO) 45 A max Miniature circuit breaker (MCB) 63 A max
Number of ways	18 ways (outgoer) 1 way (incomer) - 3P + N + E
Outgoer Pole capacity	54 x 18 mm
Length	746 mm
Width	350 mm
Depth	105 mm

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	11.5 cm
Package 1 Width	39.0 cm
Package 1 Length	76.0 cm
Package 1 Weight	7.625 kg
Unit Type of Package 2	PAM
Number of Units in Package 2	24
Package 2 Height	112.0 cm
Package 2 Width	100.0 cm
Package 2 Length	120.0 cm
Package 2 Weight	203.0 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Halogen content performance	Halogen free plastic parts product