


## Product data sheet

### Characteristics

# SEA9BN4PEV

Acti9, Isoabar B - pan assembly - 4 ways TP + earth + neutral

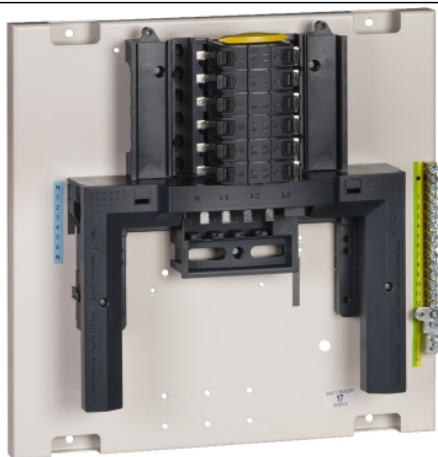

### Main

Range	Acti9
Product or component type	Pan assembly
Device application	Distribution

### Complementary

Range compatibility	Acti 9 (Acti9 Isoabar B) distribution board
Provided equipment	Grounding bar Neutral bar Mounting plate DIN rail
[In] rated current	250 A
Incomer device options	4P switch disconnecter 4P terminal block 3P + N RCCB 3P + N MCCB 4P contactor
Protection device options at outgoer	Residual current circuit breaker with overcurrent protection (RCBO) 45 A max Miniature circuit breaker (MCB) 63 A max
Number of ways	1 way (incomer) - 3P + N + E 4 ways (outgoer)
Outgoer Pole capacity	12 x 18 mm
Length	346 mm
Width	350 mm
Depth	105 mm

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	8.0 cm
Package 1 Width	15.5 cm
Package 1 Length	21.0 cm
Package 1 Weight	3.16 kg

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Halogen content performance	Halogen free plastic parts product