


Product data sheet

Characteristics

SEA9BN4TNA

Acti9, IsoBar B - panel fixing pan assembly - 4 ways TP&N

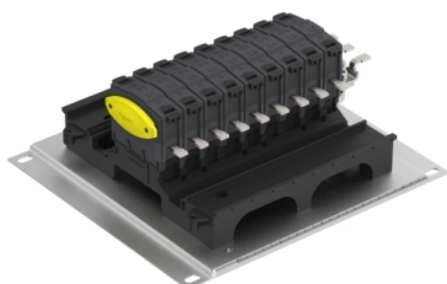

Main

Range	Acti9
Product or component type	Pan assembly
Device application	Distribution

Complementary

Range compatibility	Acti 9 (Acti9 IsoBar B) distribution board
Provided equipment	Mounting plate
[In] rated current	250 A
Incomer device options	3P switch disconnecter 3P terminal block 3P MCCB
Protection device options at outgoer	Residual current circuit breaker with overcurrent protection (RCBO) 45 A max Miniature circuit breaker (MCB) 63 A max
Number of ways	1 way (incomer) - 3P + N 4 ways (outgoer)
Outgoer Pole capacity	12 x 18 mm
Length	182 mm
Width	210 mm
Depth	90 mm

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	11.5 cm
Package 1 Width	19.5 cm
Package 1 Length	22.5 cm
Package 1 Weight	1.2 kg
Unit Type of Package 2	PAM
Number of Units in Package 2	200
Package 2 Height	112.0 cm
Package 2 Width	100.0 cm
Package 2 Length	120.0 cm
Package 2 Weight	260.0 kg

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins
Halogen content performance	Halogen free plastic parts product