


## Product data sheet

### Characteristics

# SEA9BN8PEV

Acti9, IsoBar B - pan assembly - 8 ways TP + earth + neutral

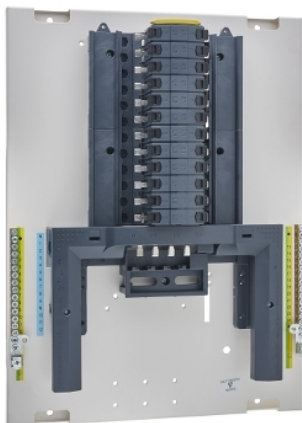

### Main

Range	Acti9
Product or component type	Pan assembly
Device application	Distribution

### Complementary

Range compatibility	Acti 9 (Acti9 IsoBar B) distribution board
Provided equipment	Neutral bar Grounding bar DIN rail Mounting plate
[In] rated current	250 A
Incomer device options	4P switch disconnecter 4P terminal block 3P + N RCCB 3P + N MCCB 4P contactor
Protection device options at outgoer	Residual current circuit breaker with overcurrent protection (RCBO) 45 A max Miniature circuit breaker (MCB) 63 A max
Number of ways	8 ways (outgoer) 1 way (incomer) - 3P + N + E
Outgoer Pole capacity	24 x 18 mm
Length	471 mm
Width	350 mm
Depth	105 mm

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	11.0 cm
Package 1 Width	39.0 cm
Package 1 Length	49.0 cm
Package 1 Weight	4.246 kg
Unit Type of Package 2	PAM
Number of Units in Package 2	48
Package 2 Height	112.0 cm
Package 2 Width	100.0 cm
Package 2 Length	120.0 cm
Package 2 Weight	218.808 kg

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
RoHS exemption information	<a href="#">Yes</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Halogen content performance	Halogen free plastic parts product