


Product data sheet

Characteristics

VW3A31208

Altivar 312, CANopen daisy chain communication card, 1 Mbps

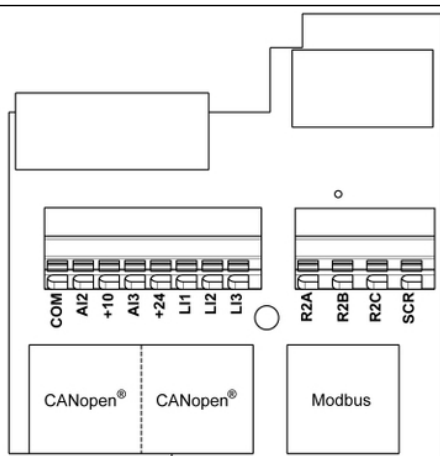

Main

Product or component type	Communication card
Range compatibility	Altivar 312 Altivar 312 Solar
Communication port protocol	CANopen daisy chain
Electrical connection	1 connector RJ45, Modbus 1 removable screw terminal block for inputs/outputs 2 connectors RJ45, CANopen
Transmission rate	10, 20, 50, 125, 250, 500 kbps or 1 Mbps
Number of addresses	1...127

Complementary

Input/output number	AI2 and AI3: 2 analog input LI1...LI3: 3 logic input R2: 1 relay output
Physical interface	RS485 multidrop serial link
Transmission frame	RTU
Communication service	PDO 6 : can be configured, asynchronous, synchronous, cyclic asynchronous 1 receive SDO + 1 transmit SDO CiA 402 profile PDO 1 : cannot be configured, asynchronous Communication monitoring node guarding and heartbeat
Net weight	0.2 kg

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.11 cm
Package 1 Width	22.86 cm
Package 1 Length	17.02 cm
Package 1 Weight	0.16 kg
Unit Type of Package 2	P06
Number of Units in Package 2	60
Package 2 Height	73.5 cm
Package 2 Width	60 cm
Package 2 Length	80 cm
Package 2 Weight	21.58 kg

Offer Sustainability

REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes

Contractual warranty

Warranty	18 months
----------	-----------