

VW3A7701

Altivar 320, Braking resistor, IP20, 100Ohm,
50W



Main

| | |
|-----------------------|---|
| Range of product | Altivar |
| Range compatibility | Altivar 312 Altivar 61 Altivar 312 Solar Altivar 32 Altivar 31C |
| Product compatibility | ATV31C018M2 ATV31C037M2 ATV31C037N4 ATV31C055M2 ATV31C055N4 ATV31C075M2 ATV31C075N4 ATV31CU11M2 ATV31CU11N4 ATV31CU15M2 ATV31CU15N4 ATV31CU22N4 Variable speed drive ATV310 at 1.5 kW Variable speed drive ATV310 at 2.2 kW ATV31CU30N4 ATV31CU40N4 Variable speed drive ATV310 at 3 kW Variable speed drive ATV310 at 4 kW ATV12H018F1 ATV12H018M2 ATV12H018M3 ATV12H037F1 ATV12H037M2 ATV12H037M3 ATV12H055M2 ATV12H075F1 ATV12H075M2 ATV12H075M3 ATV12HU15M2 ATV12HU15M3 ATV12P037F1 ATV12P037M2 ATV12P037M3 ATV12P055M2 ATV12P075M2 ATV12P075M3 ATV12PU15M3 ATV312H018M2 ATV312H018M3 ATV312H037M2 ATV312H037M3 ATV312H037N4 ATV312H055M2 ATV312H055M3 ATV312H055N4 ATV312H075M2 ATV312H075M3 ATV312H075N4 ATV312HU11M2 ATV312HU11M3 ATV312HU11N4 ATV312HU15M2 ATV312HU15M3 ATV312HU15N4 ATV312HU22N4 ATV312HU30N4 ATV312HU40N4 ATV32H018M2 ATV32H037M2 ATV32H037N4 ATV32H055M2 ATV32H055N4 ATV32H075M2 ATV32H075N4 ATV32HU11M2 ATV32HU11N4 ATV32HU15M2 ATV32HU15N4 ATV32HU22N4 ATV32HU30N4 ATV32HU40N4 ATV61H075M3 ATV61H075N4 ATV61HU15N4 ATV61HU30N4 |

| | |
|--------------------------------|-------------------------------------|
| [Ue] rated operational voltage | 24 V DC at 0.1 A 250 V AC at 1 A |
|--------------------------------|-------------------------------------|

Complementary

| | |
|--|---|
| Average power available | 50 W at 50 °C 58 W at 40 °C |
| Electrical connection | Terminal, connection capacity: <= 1.5 mm ² / AWG 16 for temperature control switch Terminal, connection capacity: <= 4 mm ² / AWG 28 for drive |
| Temperature controlled switch contact resistance | 60 µOhm |
| Protection type | Thermal protection via drive or temperature control switch at 120 °C |
| Width | 95 mm |
| Height | 293 mm |
| Depth | 95 mm |
| Net weight | 1.9 kg |

Environment

| | |
|---------------------------------------|-------------|
| IP degree of protection | IP20 |
| Ambient air temperature for storage | -25...70 °C |
| Ambient air temperature for operation | 0...50 °C |

Packing Units

| | |
|------------------------------|-----------|
| Unit Type of Package 1 | PCE |
| Number of Units in Package 1 | 1 |
| Package 1 Height | 21.0 cm |
| Package 1 Width | 38.8 cm |
| Package 1 Length | 20.0 cm |
| Package 1 Weight | 1.957 kg |
| Unit Type of Package 2 | P06 |
| Number of Units in Package 2 | 9 |
| Package 2 Height | 73.5 cm |
| Package 2 Width | 80.0 cm |
| Package 2 Length | 60.0 cm |
| Package 2 Weight | 30.442 kg |


Offer Sustainability

| | |
|----------------------------|--|
| REACH Regulation | REACH Declaration |
| REACH free of SVHC | Yes |
| EU RoHS Directive | Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration |
| Toxic heavy metal free | Yes |
| Mercury free | Yes |
| China RoHS Regulation | China RoHS Declaration |
| RoHS exemption information | Yes |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Dimensions

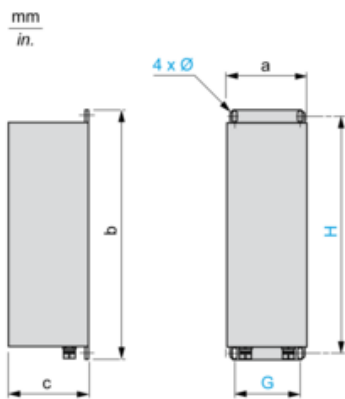

Dimensions in mm

| a | b | c | G | H | Ø |
|----|-----|----|----|-----|--------|
| 95 | 293 | 95 | 70 | 275 | 6 x 12 |

Dimensions in in.

| a | b | c | G | H | Ø |
|------|-------|------|------|-------|-------------|
| 3.74 | 11.53 | 3.74 | 2.75 | 10.82 | 0.24 X 0.47 |

Clearance

