


4061E2PUDM-TR

Clipsal Saturn 4000, PushButton Integrally Switched Universal Dimmer, 350VA

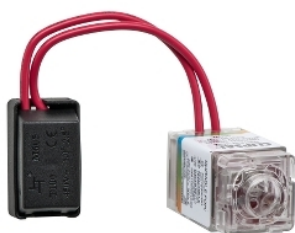

Main

Range of product	Saturn Series 4000
Product brand	Clipsal
Device presentation	Basic element with full cover plate
Dimmer type	Universal

Complementary

Power consumption in VA	350 VA
Network frequency	50 Hz
Function available	With light value memory
Actuator	Push-button
Mounting support	Wall
Width	75 mm
Height	116 mm
Depth	46 mm
Embedding depth	34 mm

Environment

Standards	AS/NZS 3100 IEC 60669-2-1 AS/NZS CISPR 15 IEC 61000-3-2
-----------	--

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	2.3 cm
Package 1 Width	8 cm
Package 1 Length	10 cm
Package 1 Weight	40 g
Unit Type of Package 2	CAR
Number of Units in Package 2	100
Package 2 Height	13.5 cm
Package 2 Width	37.5 cm
Package 2 Length	40.5 cm
Package 2 Weight	6808 g

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information