


Product data sheet

Characteristics

5504GI

C-Bus - general input unit - 4 channel

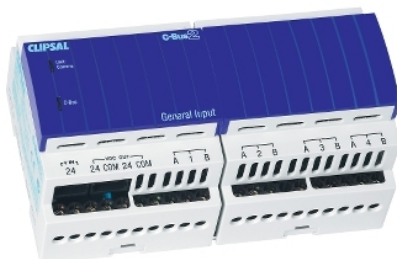

Main

Range	C-Bus
Product brand	Clipsal
Product or component type	Input module
Device application	Connection

Complementary

Number of modules	8
[Us] rated supply voltage	Supply circuit: 16...27 V AC/DC 50/60 Hz, <0.061 A Communication bus: 15...36 V DC, <0.018 A
Number of inputs	4
Output voltage	24 V DC (+/- 10 %), 0.25 A
Analogue input type	Configurable voltage, current or probe 0...1 V 100 kOhm input voltage Configurable voltage, current or probe 0...5 V 100 kOhm input voltage Configurable voltage, current or probe 0...10 V 100 kOhm input voltage Configurable voltage, current or probe 0...20 mA 249 Ohm Configurable voltage, current or probe 4...20 mA 249 Ohm Configurable voltage, current or probe 0...10000 Ohm connection of probes Configurable voltage, current or probe 0...20 V 100 kOhm input voltage Configurable voltage, current or probe 0...500 Ohm connection of probes Configurable voltage, current or probe 0...1000 Ohm connection of probes Configurable voltage, current or probe 0...3000 Ohm connection of probes
Mounting support	DIN rail
Width	143 mm
Height	85 mm
Depth	65 mm
Net weight	190 g


Environment

IP degree of protection	IP20
Ambient air temperature for operation	0...45 °C

Packing Units

Package 1 Weight	920.000 g
Package 1 Height	98.000 mm
Package 1 width	107.000 mm
Package 1 Length	224.000 mm

Offer Sustainability

EU RoHS Directive	Not compliant
China RoHS Regulation	 China RoHS Declaration