


Product data sheet

Characteristics

PDL348PB6TMBT-VW

PDL Iconic 6A 240V pushbutton timer mechanism, 3 wire with ControlLink

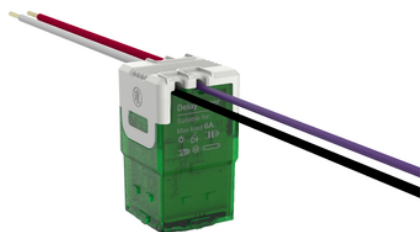

Main

Range	PDL Iconic
Product or component type	Timer
Device presentation	Mechanism

Complementary

Device mounting	Flush
Actuator	Push-button
Fixing mode	Clip-in
Colour tint	Vivid white
Surface finish	Matt
Type of packing	Box
Sale per indivisible quantity	1
Time delay	1...86400 s (24 h) adjustable
Remote control type	Push-button Wiser room application
[Ue] rated operational voltage	240 V AC 50 Hz
Load type	LED lighting 6 A Incandescent lamp 6 A Low voltage halogen lamp with iron core transformer 6 A Low voltage halogen lamp with electronic transformer 6 A Fluorescent lamp 6 A Compact fluorescent lamp 6 A Resistive 6 A
Power range	> 0 W
Derating factor	1 devices 6 A without derating 2 devices 4.5 A with derating factor 3 devices 4 A with derating factor 4 devices 3 A with derating factor 5 devices 2 A with derating factor 6 devices 1.5 A with derating factor
Operating distance	30 m
Control signal type	ControlLink
Connections - terminals	Screw terminals
Number of terminals	4
Wiring configuration	3 wires with neutral
Screwdriver shape	Square drive no 1 (SQ1) Phillips
Local signalling	LED indicator (warm white)
Material	PC (UL94 V-2): top PC MAS056 (UL94 V-2): bottom

Height	23 mm
Width	23 mm
Depth	40 mm
Embedding depth	38 mm
Standards	AS/NZS 60669.2.1

Environment

Ambient air temperature for storage	0...60 °C
Ambient air temperature for operation	0...45 °C
Relative humidity	0...90 %

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.9 cm
Package 1 Width	6.7 cm
Package 1 Length	8.7 cm
Package 1 Weight	63 g

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant with Exemptions
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information